

RGX Series

SCBA Couplings


NFPA 1981



Durability in extreme environments:

Parker's RGX Series couplings are built to withstand the extreme temperature environment that is required of the self contained breathing apparatus (SCBA) widely used in the fire rescue community. Beyond meeting the dimensional and performance specifications set by the National Fire Protection Association (NFPA), these couplings also function in colder temperatures than required by the industry standard. Parker's robust seal design promotes longer service life and provides increased durability.

Made in the USA, RGX Series quick couplings are directly interchangeable with existing couplings manufactured to the NFPA 1981 requirements. Additionally, RGX series' protective caps meet the heat and flame resistance specifications of that standard.

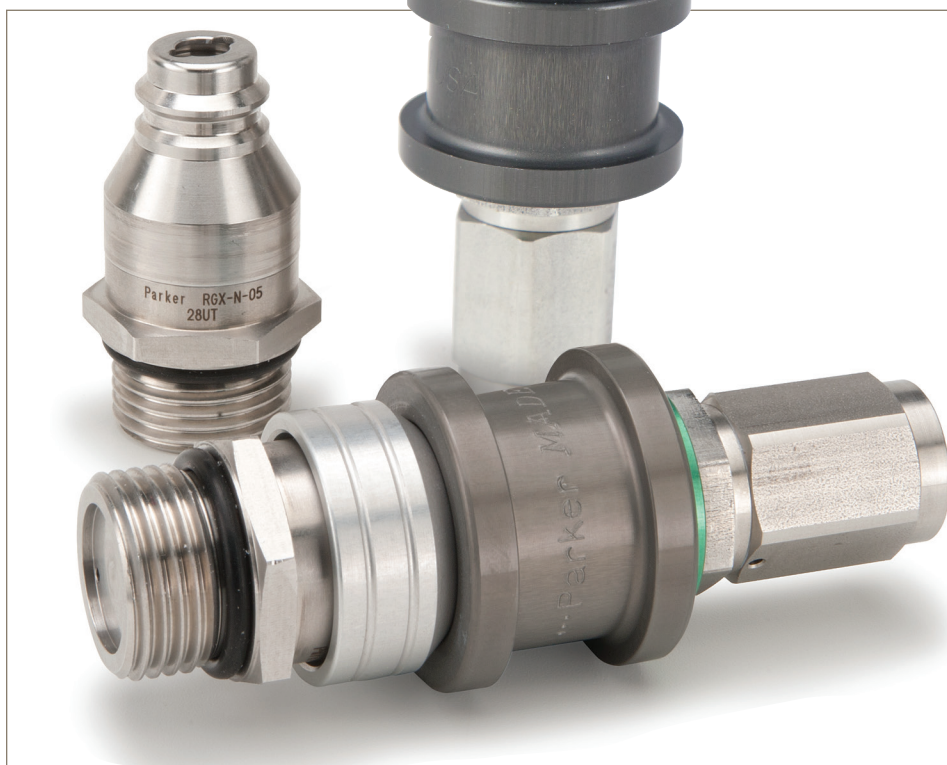

Contact Information:

Parker Hannifin Corporation
Quick Coupling Division
8145 Lewis Road
Minneapolis, MN 55427

Todd Lambert
tlambert@parker.com
phone 763 544 7781
fax 763 544 3418
www.parker.com/quickcouplings

RGX Series Features:

- Push to connect operation
- Visual connection indicator
- Meets National Fire Protection Association standards
- Interchanges with similar industry standard couplings
- Exceeds industry standards for temperature range
- Lightweight design
- Rugged and durable
- Keyed and colored options






ENGINEERING YOUR SUCCESS.

RGX Series Specifications



RGX Series Specs

Rated Pressure	Temp. Range	Material
5,500 psig	-40° F to +250° F	Stainless Steel

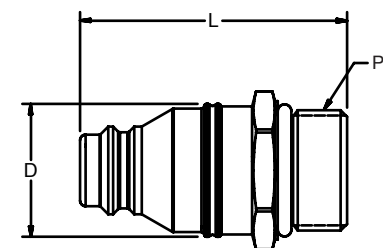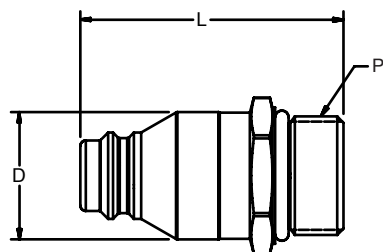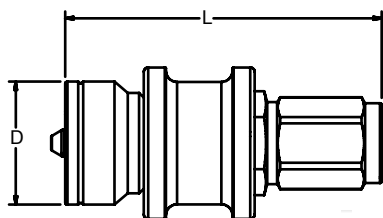

Couplers

Coupler Part No.	Port	Diameter	Length	Keyed/Color Options
RGX-C-03-BL	7/16-20 UNF-2B	1.10"	2.85"	Black
RGX-C-03-BU	7/16-20 UNF-2B	1.10"	2.85"	Blue
RGX-C-03-CL	7/16-20 UNF-2B	1.15"	2.85"	Clear
RGX-C-03-RD	7/16-20 UNF-2B	1.15"	2.85"	Red

Nipple

Nipple Part No.	Port	Diameter	Length
RGX-N-05	7/8-14 UNF-2A	.93"	1.93"
RGX-N-19	7/8-14 UNF-2A	.93"	1.93"
RGX-N-22	7/8-14 UNF-2A (with protrusion)	.93"	1.93"

Nipple

Nipple Part No.	Port	Diameter	Length
RGX-N-06	7/8-14 UNF-2A	.96"	1.93"

Protective Caps

Cap Part No.	Cap Option	Length
RGX-CAP-07	Nipple Cap	8.50"
RGX-CAP-02	Coupler Cap	5.80"

